


Module SFP 1000BASE-T

Article number: 11008781

overview

- SFP module
- 1000base-T connection
- RJ45 connector

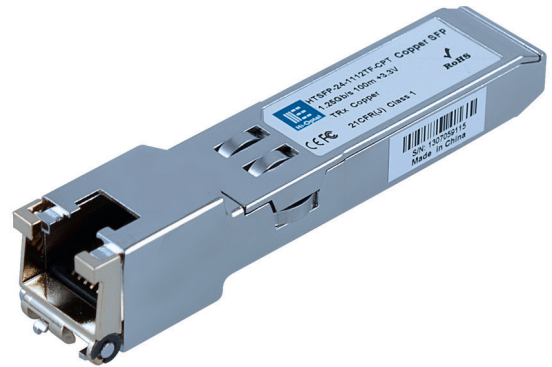

technical data

general data

| | |
|--------------------------|---------------------|
| manufacturer | Hi-Optel |
| manufacturer designation | HTSFP-24-1112TF-CPT |

interface

| | |
|-----------------|-----------------|
| data interface | GigE |
| Ethernet type | 100/1000 BASE-T |
| number of ports | 1 |
| ports | RJ45 |

interface

| | |
|---------------|------------|
| standard | IEEE802.3 |
| transfer rate | 1,0 Gb/s |
| distance | max. 100 m |

environmental conditions

| | |
|-----------------------|-------------------|
| operating temperature | 0 ... +70 °C |
| conformity | CE FCC RoHS |