


Shielded cable 3 wires, 10,0 m

Article number: 11002561

overview

- shielded power cable
- M8/3-pin female connector to open wires
- cable carrier compatible
- length 10,0 m

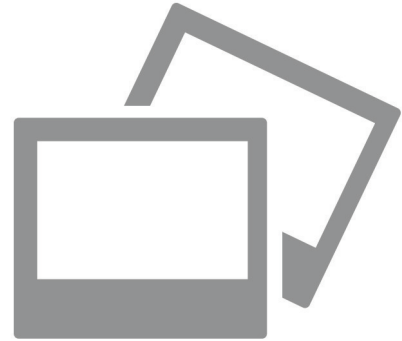

technical data

electrical data

shielding	yes
number of poles	3
connectors	M8 female connector, screw lock open wires

mechanical data

bending radius moved in- stallation	46 mm
use in cable carriers	yes
cable length [m]	10 m
weight	≤ 345 g

mechanical data

material	PUR
----------	-----

interface

data interface	process interface
----------------	-------------------


environmental conditions

flame resistance	VDE0472 part 804/B
resistance to oil	VDE 0472 part 803
operation temperature (static)	-50 ... +80 °C
protection class	IP 67 (camera side)

Shielded cable 3 wires, 10,0 m

Article number: 11002561

pin assignment

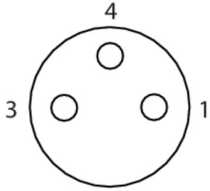

M8	color
1:	BN
4:	BK
3:	BU