

# Shielded cable 4 wires, 5,0 m

Article number: 10170032

## overview

- shielded process interface cable (trigger and flash)
- M8/4-pin female connector to open wires
- cable carrier compatible
- length 5,0 m



## technical data

### electrical data

shielding	yes
number of poles	4
connectors	M8 female connector, screw lock open wires

### mechanical data

bending radius static	25 mm
bending radius moved in-stallation	63 mm
bending cycles	250000
use in cable carriers	yes
cable length [m]	5 m
weight	≤ 202 g
material	PUR


### interface

data interface	process interface
----------------	-------------------

### environmental conditions

flame resistance	DIN EN 60332-2-2 VDE 0482-332-2-2 IEC 60332-2-2 UL/CSA FT-2
halogen-free	EN 50267-2-1 IEC 60754-1 VDE 0482-267-2-1
operation temperature (static)	-25 ... +60 °C
protection class	IP 67 (camera side)

pin assignment

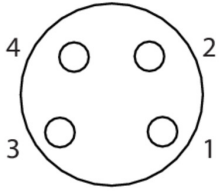

M8	color
1:	BN
2:	WH
4:	BK
3:	BU