

Shielded cable 4 wires, 5,0 m

Article number: 10170032

Overview

- shielded process interface cable (trigger and flash)
- M8/4-pin female connector to open wires
- cable carrier compatible
- length 5,0 m



Picture similar

Technical data

Electrical data

Shielding	yes
Number of poles	4
Connectors	M8 female connector, screw lock open wires

Mechanical data

Smallest bending radius static	25 mm
Smallest bending radius moved installation	63 mm
Bending cycles	250000
Use in cable carriers	yes
Cable length [m]	5 m
Weight	≤ 202 g

Mechanical data

Material	PUR
----------	-----

Interface

Data interface	Process interface
----------------	-------------------


Environmental conditions

Flame resistance	DIN EN 60332-2-2 VDE 0482-332-2-2 IEC 60332-2-2 UL/CSA FT-2
Halogen-free	EN 50267-2-1 IEC 60754-1 VDE 0482-267-2-1
Operation temperature (static)	-25 ... +60 °C
Protection class	IP 67 (camera side)

Shielded cable 4 wires, 5,0 m

Article number: 10170032

Pin assignment

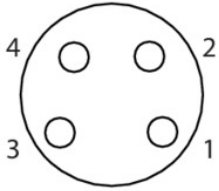

M8	color
1:	BN
2:	WH
4:	BK
3:	BU