


Tube M62 V4A scratchproof glass

Article number: 11704018

Overview

- stainless steel lens protection with scratchproof laminated safety glass: Corning® Gorilla® glass (generation 3)
- optional tube extension with Tube Module 6mm M62 V4A (11704016), Tube Module 12 mm M62 V4A (11704015) or Tube Module 36 mm M62 V4A (11704015). Use of several Tube Modules possible.
- thread: M62
- length 58 mm

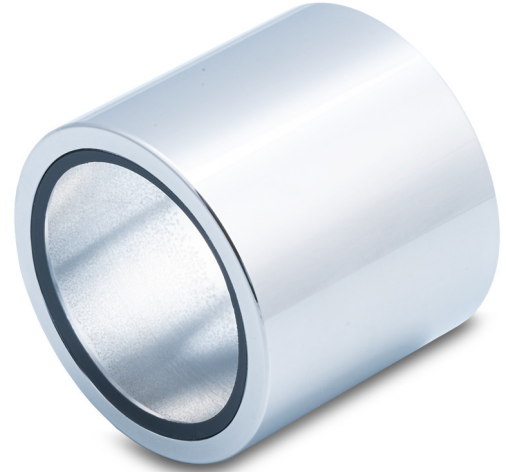

Technical data


Mechanical data

Inner diameter	61 mm
External diameter	65 mm
Material of cover glass	Corning® Gorilla® glass
Weight	≤ 195 g

Mechanical data

Thread	M62 × 0,75
Ø cover glass	50 mm
Length of tube	58 mm
Material	Stainless steel 1.4404
Sealing	Gomastit 400

Dimension drawing

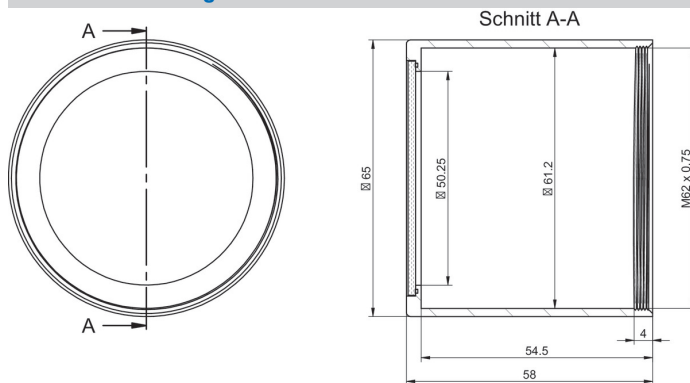

Principle

