


## Z-ESG 32DH0500G

Shielded cable 6 wires, 5,0 m

Article number: 11098904

### overview

- shielded process interface and power cable for Baumer *VisiLine*® cameras
- M8/6-pin female connector to open wires
- cable carrier compatible
- length 5,0 m

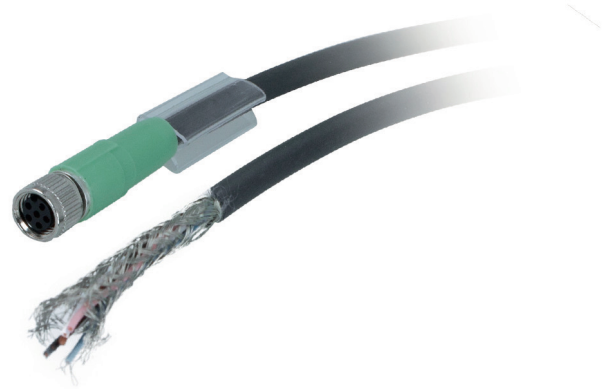

### technical data

#### electrical data

shielding	yes
number of poles	6
connectors	M8 female connector, screw lock

#### mechanical data

bending radius static	52 mm
bending radius moved in-stallation	52 mm
bending cycles	4000000
use in cable carriers	yes
cable length [m]	5 m

#### mechanical data

weight	≤ 187 g
material	PUR, halogen-free

#### interface

data interface	process interface
----------------	-------------------

#### environmental conditions


flame resistance	DIN UL-Style 20549
halogen-free	DIN VDE 0472 part 815
resistance to oil	DIN EN 60811-2-1
operation temperature (static)	-5 ... +80 °C
protection class	IP 65/67 (camera side)

## Z-ESG 32DH0500G

Shielded cable 6 wires, 5,0 m

Article number: 11098904

### pin assignment

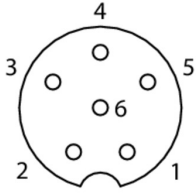

M8	color	M8	color
1:	BN	4:	BK
2:	WH	5:	GY
3:	BU	6:	PK