

## Z-ESG 32FP0500G

Shielded cable 8 wires, female connector, 5,0 m

Article number: 11118810

### Overview

- shielded process interface cable
- M8/8-pin female connector to open wires
- cable carrier compatible
- length 5,0 m



### Technical data

#### Electrical data

Shielding	yes
Number of poles	8
Connectors	M8 female connector, screw lock

#### Mechanical data

Smallest bending radius static	29.5 mm
Smallest bending radius moved installation	59 mm
Bending cycles	2000000
Use in cable carriers	yes
Cable length [m]	5 m
Weight	≤ 246 g
Material	PUR, halogen-free

#### Interface

Data interface	Process interface
----------------	-------------------

#### Environmental conditions


Flame resistance	DIN EN 60332-1-2 VDE 0482-332-1-2 IEC 60332-1-2 CSA FT-2
Halogen-free	DIN EN 50267-2-1 IEC 60754-1 VDE 0482-267-2-1
Resistance to oil	DIN EN 60811-2-1, 168 h at 100°C
Operation temperature (static)	-50 ... +80 °C
Protection class	IP 65/67 (camera side)

## Z-ESG 32FP0500G

Shielded cable 8 wires, female connector, 5,0 m

Article number: 11118810

### Pin assignment

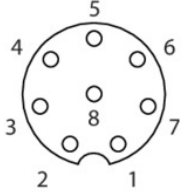

M8	wire color	M8	wire color
1:	WH	5:	GY
2:	BN	6:	PK
3:	GN	7:	BU
4:	YE	8:	RD