

Z-ESW 31DH0500G

90° Shielded Cable, 6 wires, 5,0 m

Article number: 11105041

overview

- shielded process interface and power cable for Baumer *VisiLine*® cameras
- 90° angled M8/6-pin female connector to open wires
- cable carrier compatible
- length 5,0 m
- Phase-Out starting 08/20, alternative via sales



technical data

electrical data

shielding	yes
number of poles	6
connectors	M8 female connector, angled, screw lock

mechanical data

smallest bending radius static	52 mm
smallest bending radius moved installation	52 mm
bending cycles	4000000

mechanical data

use in cable carriers	yes
cable length [m]	5 m
weight	≤ 194 g
material	PUR, halogen-free

interface

data interface	process interface
----------------	-------------------

environmental conditions


resistance to oil	DIN EN 60811-2-1
protection class	IP 65/67 (camera side)

Z-ESW 31DH0500G

90° Shielded Cable, 6 wires, 5,0 m

Article number: 11105041

pin assignment

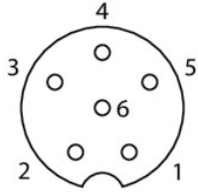

M8	color	M8	color
1:	BN	4:	BK
2:	WH	5:	GY
3:	BU	6:	PK