

## Z-ESW 31DH0500G

90° Shielded Cable, 6 wires, 5,0 m

Article number: 11105041

### Overview

- shielded process interface and power cable for Baumer *VisiLine*® cameras
- 90° angled M8/6-pin female connector to open wires
- cable carrier compatible
- length 5,0 m



*Picture similar*

### Technical data

#### Electrical data

Shielding	yes
Number of poles	6
Connectors	M8 female connector, angled, screw lock

#### Mechanical data

Smallest bending radius static	52 mm
Smallest bending radius moved installation	52 mm
Bending cycles	4000000

#### Mechanical data

Use in cable carriers	yes
Cable length [m]	5 m
Weight	≤ 194 g
Material	PUR, halogen-free

#### Interface

Data interface	Process interface
----------------	-------------------

#### Environmental conditions


Resistance to oil	DIN EN 60811-2-1
Protection class	IP 65/67 (camera side)

# Z-ESW 31DH0500G

90° Shielded Cable, 6 wires, 5,0 m

Article number: 11105041

## Pin assignment

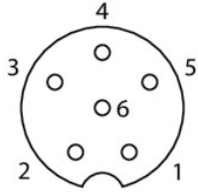

M8	color	M8	color
1:	BN	4:	BK
2:	WH	5:	GY
3:	BU	6:	PK