


## Z-ESW 31FH0500

90° Cable 8 wires, 5,0 m

Article number: 11105262

### overview

- process interface cable
- 90° angled M8/8-pin female connector to open wires
- length 5,0 m

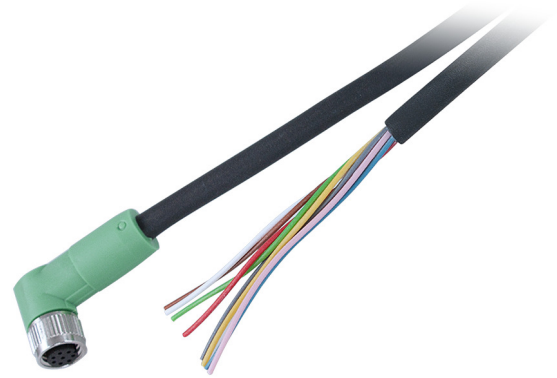

### technical data

#### electrical data

shielding	no
number of poles	8
connectors	M8 female connector, angled, screw lock

#### mechanical data

smallest bending radius static	26 mm
smallest bending radius moved installation	52 mm
use in cable carriers	no
cable length [m]	5 m
weight	≤ 175 g

#### mechanical data

material	PUR
----------	-----

#### interface

data interface	process interface
----------------	-------------------

#### environmental conditions


flame resistance	UL 758/1581 (horizontal) UL 758/1581 FT2
halogen-free	DIN VDE 0472 part 815 DIN EN 50267-2-1
resistance to oil	DIN EN 60811-2-1, 168 h at 100°C
operation temperature (static)	-25 ... +80 °C
protection class	IP 65/67/68 (camera side)

## Z-ESW 31FH0500

90° Cable 8 wires, 5,0 m

Article number: 11105262

### pin assignment

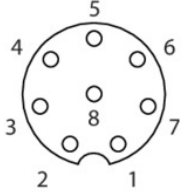

M8	wire color	M8	wire color
1:	WH	5:	GY
2:	BN	6:	PK
3:	GN	7:	BU
4:	YE	8:	RD