

## Z-KSG 34A/KSG45AC0500G/E

Ethernet cable for cable carriers, 5,0 m

Article number: 11120360

### overview

- shielded Ethernet cable
- straight M12/4-pin male connector to RJ45
- cable carrier compatible
- length 5,0 m
- Phase-Out starting 08/20, alternative via sales



### technical data

#### electrical data

number of poles	4
connectors	M12 connector, screw lock RJ45

#### mechanical data

smallest bending radius static	31 mm
smallest bending radius moved installation	62 mm
bending cycles	1000000
use in cable carriers	yes
cable length [m]	5 m
weight	≤ 300 g

#### mechanical data

material	PUR
----------	-----

#### interface

data interface	Ethernet
----------------	----------

#### environmental conditions


flame resistance	UL 758/1581 (horizontal) UL 758/1581 FT2
halogen-free	DIN VDE 0472 part 815 DIN EN 50267-2-1
resistance to oil	DIN EN 60811-2-1
operation temperature (static)	-50 ... +80 °C
protection class	IP 67 (camera side)

# Z-KSG 34A/KSG45AC0500G/E

Ethernet cable for cable carriers, 5,0 m

Article number: 11120360

## pin assignment

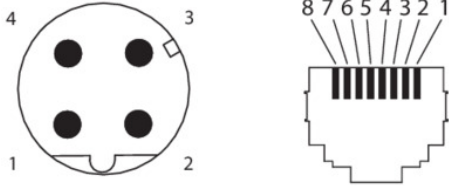

M12	RJ45
1:	1
3:	2
2:	3
4:	6