

## ZVI-HIGHLIGHT120\_24VDC\_WEIß

HI-LIGHT-120 white 24VDC with M8 connector

Article number: 11130182

### overview

- flashable LED back light
- white
- diffuse
- radiation angle 120°
- diameter: 94 mm
- M8/4-pin connector (cable has to be ordered separately)
- dimensions: 127 mm × 127 mm × 20 mm housing



### technical data

#### general data

manufacturer Büchner Lichtsysteme GmbH

#### illumination data

color white  
illumination characteristic diffuse

#### electrical data

number of poles 4  
illumination connector • M8 connector  
current 0,6 A  
current at flash mode ≤ 1,3 A  
voltage at flash mode ≤ 48 V DC

#### electrical data

duty cycle 0-10%  
maximum flash duration 1 ms

#### mechanical data

construction design back light  
dimensions 127 mm × 127 mm × 20 mm  
height 9,5 mm  
material of cover glass acrylic  
weight ≤ 355 g  
material aluminum (shot-peened, anodized)

#### environmental conditions


operating temperature max. 50 °C

## ZVI-HILIGHT120\_24VDC\_WEIß

HI-LIGHT-120 white 24VDC with M8 connector

Article number: 11130182

### pin assignment

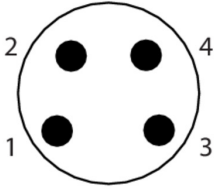

M8	signal
1:	LED +24V (pulsing 24-48 V)
2:	N.C.
3:	LED - (GND)
4:	N.C.