

ZVI-HIGHLIGHT120_24VDC_WEIß

HI-LIGHT-120 white 24VDC with M8 connector

Article number: 11130182

overview

- flashable LED back light
- white
- diffuse
- radiation angle 120°
- diameter: 94 mm
- 24 V
- voltage-driven (equipped with integrated pre-resistor)
- M8/4-pin connector (cable has to be ordered separately)
- dimensions: 127 mm × 127 mm × 20 mm housing



technical data

general data

manufacturer BÜchner Lichtsysteme GmbH

illumination data

color white

illumination characteristic diffuse

illumination mode flashable

electrical data

connectors M8/4-pin male connector

illumination control voltage-driven (equipped with integrated pre-resistor)

current 0,6 A

current at flash mode ≤ 1,3 A

voltage at flash mode ≤ 48 V DC

electrical data

duty cycle 0-10%

maximum flash duration 1 ms

mechanical data

construction design back light

dimensions 127 mm × 127 mm × 20 mm

height 9,5 mm

material of cover glass acrylic

weight ≤ 355 g

material aluminum (shot-peened, anodized)

environmental conditions


operating temperature max. 50 °C

ZVI-HILIGHT120_24VDC_WEIß

HI-LIGHT-120 white 24VDC with M8 connector

Article number: 11130182

pin assignment

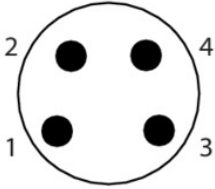

M8	signal
1:	LED +24V (pulsing 24-48 V)
2:	N.C.
3:	LED - (GND)
4:	N.C.