


overview

- Computar lens
- 6 mm
- F 2,4
- format 1/2"
- M.O.D. 0,1 m
- S-mount

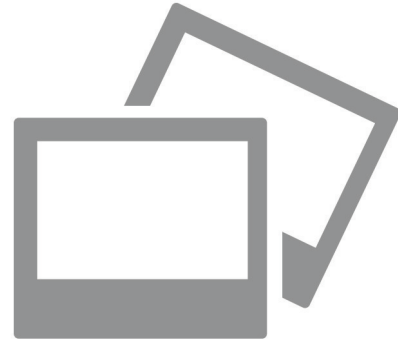

technical data

general data

manufacturer Computar

mechanical data

lens mount S-mount

dimensions 17 mm × 20,5 mm

max. length (excl. thread) 6,5 mm

weight ≤ 7 g

lens data

lens resolution 2 MP

focal length 6 mm

lens data

focal range < 12 mm

format 1/2"

aperture F2,4

M.O.D. 0,1 m

horizontal angle of view 59,1 °

vertical angle of view 45 °

diagonal angle of view 72,5 °

at image format 12.2 × 8,9 mm

environmental conditions

operating temperature -20 ... +50 °C